

Part No: 3790-790

Fabricated DWV

Sanitary Tee

Desc: 18X10 PVC RED SAN TEE SOC SCH40 N.P.R.

MSRP: 2408.29

Part Code: 390

Weight(lbs): 87.7


Weight(kg): 39.78

Weight(gm): 39780

Size: 18"X18"X10"

Color: WHITE

Material: PVC

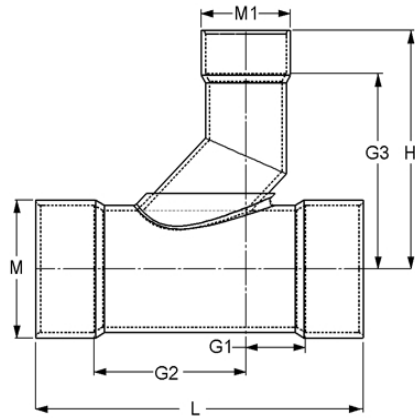

M = 19-1/8

M1 = 11-1/2

G1 = 5-7/8

G2 = 18-7/8

G3 = 22-9/16

H = 27-13/16

L = 42-3/4

Type Sch 40 DWV- Reducer

Connection Socket X Socket X Socket

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

