

Part No: 3791-080

Fabricated DWV

Sanitary Tee

Desc: 8 PVC DBL SAN TEE SOC SCH40 N.P.R.

MSRP: 536.69

Part Code: 390

Weight(lbs): 29.983

Weight(kg): 13.6

Weight(gm): 13600


Size: 8"

Color: WHITE

Material: PVC

Type SCH 40 DWV Double

Connection Socket X Socket X Socket X
Socket

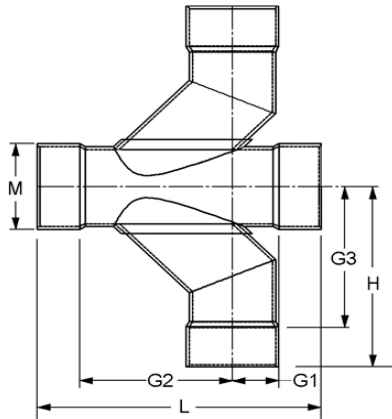

G1 = 4- 5/8

G2 = 15- 5/16

G3 = 15-3/16

H = 19-7/16

L = 28-7/16

M = 9-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

