

Part No: 3791-621

Fabricated DWV

Sanitary Tee

Desc: 10X2 PVC RED DBL SAN TEE SOC SCH40 NPR

MSRP: 437.74

Part Code: 390

Weight(lbs): 12.985


Weight(kg): 5.89

Weight(gm): 5890

Size: 10"X10"X2"X2"

Color: WHITE

Material: PVC

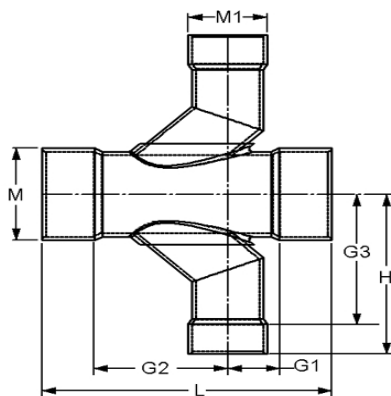

Type SCH 40 DWV Double- Reducer
Connection Socket X Socket X Socket X Socket

G1 = 3-1/2

G2 = 6-1/4

G3 = 9-7/16

H = 10-3/16

L = 20-1/4

M = 11-1/2

M1 = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

