

Part No: 3792-120

Fabricated DWV

Double Wye

Desc: 12 PVC DBL COMB WYE&1/8 BEND SOC SCH40

MSRP: 1434.49

Part Code: 390

Weight(lbs): 124.12


Weight(kg): 56.3

Weight(gm): 56300

Size: 12"

Color: WHITE

Material: PVC

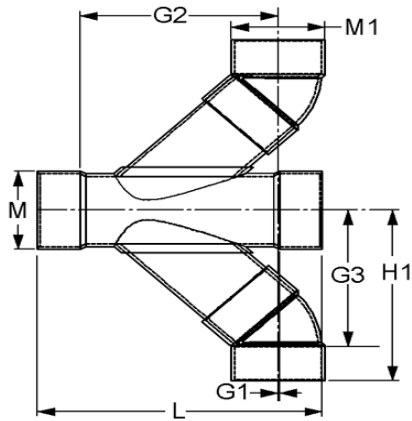

Schedule SCH 40 DWV

Type Double Combo Wye With 1/8 Bend

Connection Socket x Socket x Socket x Socket

H1 = 29-3/4

L = 39-7/8

M = 13-9/16

M1 = 14-1/4

G3 = 23-5/8

G1 = 1/2

G2 = 27-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

