

Part No: 3792-530

Fabricated DWV

Double Wye

Desc: 6X3 PVC RED DBL COMB WYE&1/8 BEND SCH40

MSRP: 260.34

Part Code: 390

Weight(lbs): 8.201


Weight(kg): 3.72

Weight(gm): 3720

Size: 6"X6"X3"X3"

Color: WHITE

Material: PVC

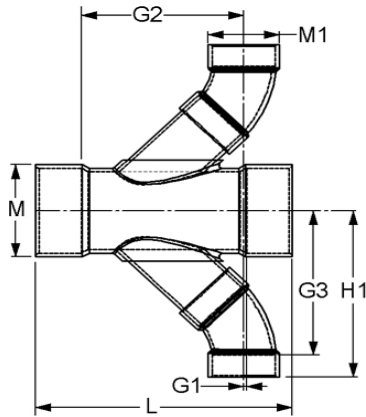

Schedule SCH 40 DWV

Type Reducing Double Combo Wye
With 1/8 Bend

Connection Socket x Socket x Socket x Socket

G1 = 3/8

G2 = 9-7/8

G3 = 9-3/4

H1 = 11-5/16

L = 16-3/4

M = 7-3/16

M1 = 4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

