

Part No: 3792-578

Fabricated DWV

Double Wye

Desc: 8X2 PVC RED DBL COMB Y&1/8 BND SOC SCH40

MSRP: 303.38

Part Code: 390

Weight(lbs): 10.981


Weight(kg): 4.981

Weight(gm): 4981

Size: 8"X8"X2"X2"

Color: WHITE

Material: PVC

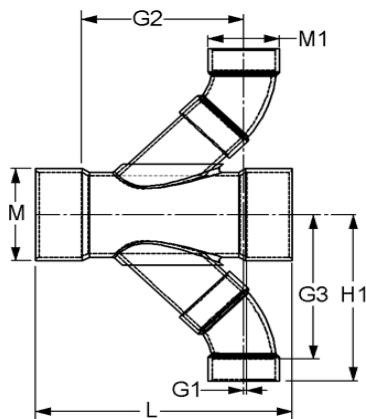

Schedule SCH 40 DWV

Type Reducing Double Combo Wye
With 1/8 Bend

Connection Socket x Socket x Socket x Socket

H1 = 10-1/16

L = 18-1/4

M = 9-1/4

M1 = 2-3/4

G3 = 9-1/4

G1 = 1-3/8

G2 = 8-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

