

Part No: 3792-663

Fabricated DWV

Double Wye

Desc: 12X3 PVC RED DBL CMB Y&1/8 BND SOC SCH40

MSRP: 746.73

Part Code: 390

Weight(lbs): 24.03


Weight(kg): 10.9

Weight(gm): 10900

Size: 12"X12"X3"X3"

Color: WHITE

Material: PVC

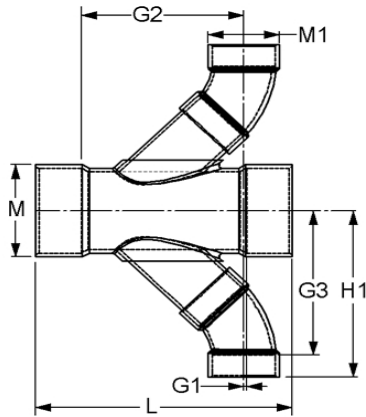

Schedule SCH 40 DWV

Type Reducing Double Combo Wye
With 1/8 Bend

Connection Socket x Socket x Socket x Socket

G1 = 1-3/8

M1 = 4

G2 = 10-5/8

G3 = 12-11/16

H1 = 14-1/4

L = 24-1/2

M = 13-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

