

Part No: 3792-691

Fabricated DWV

Double Wye

Desc: 14X2 PVC RED DBL CMB Y&1/8 BND SOC SCH40

MSRP: 997.11

Part Code: 390

Weight(lbs): 27.035


Weight(kg): 12.263

Weight(gm): 12263

Size: 14"X14"X2"X2"

Color: WHITE

Material: PVC

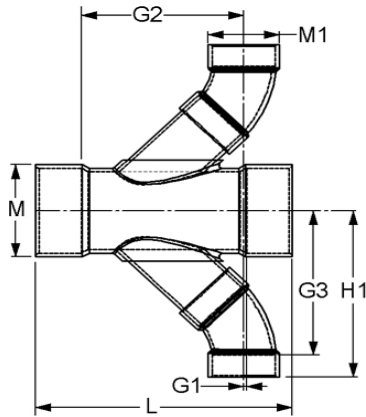

Schedule SCH 40 DWV

Type Reducing Double Combo Wye
With 1/8 Bend

Connection Socket x Socket x Socket x Socket

G1 = 1-5/8

G2 = 8-3/8

G3 = 11-13/16

H1 = 12-5/8

L = 24

M = 14-7/8

M1 = 2-3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

