

Part No: 3792-698

Fabricated DWV

Double Wye

Desc: 14X8 PVC RED DBL CMB Y&1/8 BND SOC SCH40

MSRP: 1489.73

Part Code: 390

Weight(lbs): 60.374


Weight(kg): 27.385

Weight(gm): 27385

Size: 14"X14"X8"X8"

Color: WHITE

Material: PVC

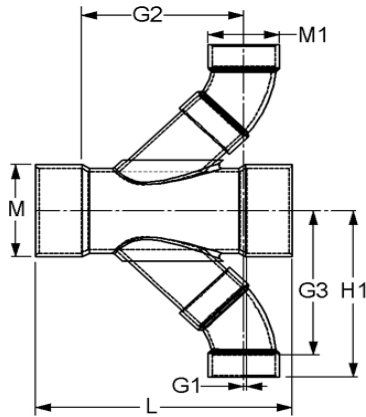

Schedule SCH 40 DWV

Type Reducing Double Combo Wye
With 1/8 Bend

Connection Socket x Socket x Socket x Socket

G1 = 5/16

G2 = 19-11/16

L = 34

M = 14-7/8

M1 = 9-3/8

H1 = 22-3/4

G3 = 18-11/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

