

Part No: 3901-100

Fabricated DWV

Tees

Desc: 10 PVC TEE SOC SCH80

MSRP: 800.58

Part Code: 400

Weight(lbs): 41.189

Weight(kg): 18.683

Weight(gm): 18683

Size: 10


Color: GRAY

Material: PVC

Type Standard Vent Tee

Schedule SCH 80 DWV

Connection Socket x Socket x Socket

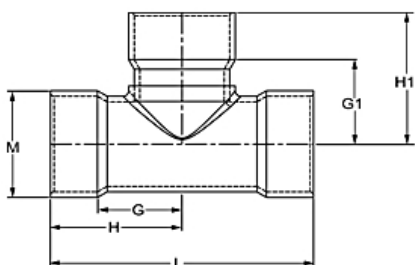

M = 11-15/16

L = 28-1/2

H1 = 14-1/4

H = 14-1/4

G1 = 9

G = 9

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

