

Part No: 3901-140CTEST

Fabricated CPVC Schedule 80 Tees DWV

Desc: 14 CPVC TEST TEE SOCXTHREAD W/PLUG SCH80

MSRP: 11471.99

Part Code: 099

Weight(lbs): 85.098

Weight(kg): 38.6

Weight(gm): 38600


Size: 14

Color: GRAY

Material: CPVC

Type Test Tee With Plug

Connection Socket X Fpt With Plug

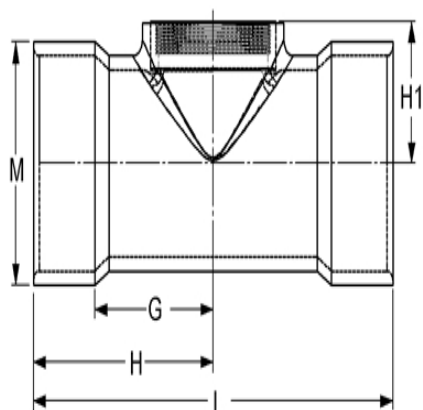

G = 12-1/4

H = 19-1/4

H1 = 8-3/4

L = 38-1/2

M = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

