

Part No: 3901-160

Fabricated DWV

Tees

Desc: 16 PVC TEE SOC SCH80

MSRP: 3120.99

Part Code: 400

Weight(lbs): 120.703

Weight(kg): 54.75

Weight(gm): 54750

Size: 16


Color: GRAY

Material: PVC

Type Standard Vent Tee

Schedule SCH 80 DWV

Connection Socket x Socket x Socket

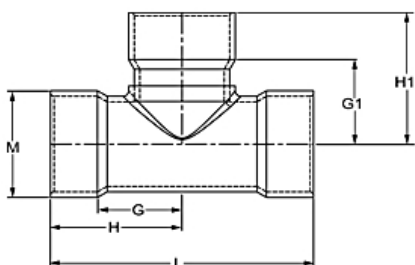

G1 = 13

G = 13

M = 17-11/16

L = 42

H1 = 21

H = 21

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

