

Part No: 3901-240C

**Fabricated CPVC Schedule 80 Tees
DWV**

Desc: 24 CPVC TEE SOC SCH80

MSRP: 35325.16

Part Code: 099

Weight(lbs): 453.407

Weight(kg): 205.662

Weight(gm): 205662


Size: 24

Color: GRAY

Material: CPVC

Type Standard

Connection Socket x Socket x Socket

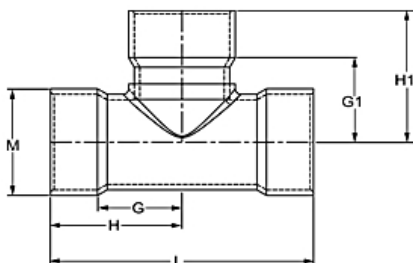

G = 20-1/4

G1 = 20-1/4

H = 32-1/4

H1 = 32-1/4

L = 64-1/4

M = 26-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

