

Part No: 3901-621C

**Fabricated CPVC Schedule 80 Tees
DWV**

Desc: 10X2 CPVC RED TEE SOC SCH80

MSRP: 1615.74

Part Code: 099

Weight(lbs): 23.892

Weight(kg): 10.837

Weight(gm): 10837


Size: 10 X 2

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket x Socket x Socket

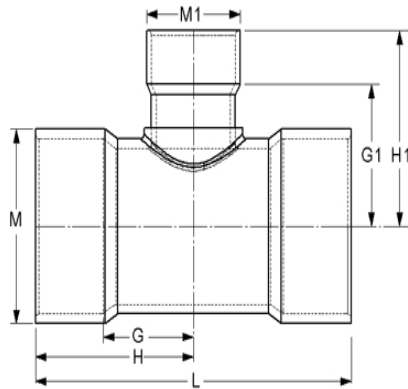

M = 11-15/16

M1 = 2-13/16

G = 4-3/8

G1 = 7-1/8

H = 9-5/8

H1 = 8-7/8

L = 19-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

