

Part No: 3901-624C

**Fabricated CPVC Schedule 80 Tees
DWV**

Desc: 10X4 CPVC RED TEE SOC SCH80

MSRP: 1699.73

Part Code: 099

Weight(lbs): 26.676

Weight(kg): 12.1

Weight(gm): 12100


Size: 10 X 4

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket x Socket x Socket

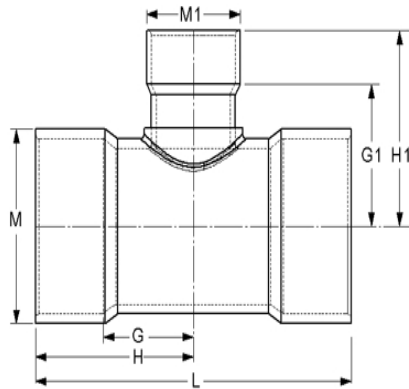

H1 = 10-15/16

L = 21-1/4

M = 11-15/16

M1 = 5-3/16

G = 5-3/8

G1 = 8-11/16

H = 10-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

