

Part No: 3901-751

Fabricated DWV

Tees

Desc: 16X2 PVC RED TEE SOC SCH80

MSRP: 1338.69

Part Code: 400

Weight(lbs): 63.339


Weight(kg): 28.73

Weight(gm): 28730

Size: 16 X 2

Color: GRAY

Material: PVC

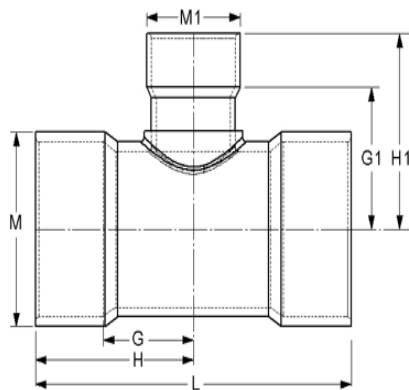

Type Reducing Vent Tee
Schedule SCH 80 DWV
Connection Socket x Socket x Socket

G = 5-7/8 **G1** = 9-1/2 **H** = 13-7/8 **H1** = 11-1/4 **L** = 27-3/4
M = 17-11/16 **M1** = 2-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

