

Part No: 3901-754

Fabricated DWV

Tees

Desc: 16X4 PVC RED TEE SOC SCH80

MSRP: 1594.27

Part Code: 400

Weight(lbs): 64.618


Weight(kg): 29.31

Weight(gm): 29310

Size: 16 X 4

Color: GRAY

Material: PVC

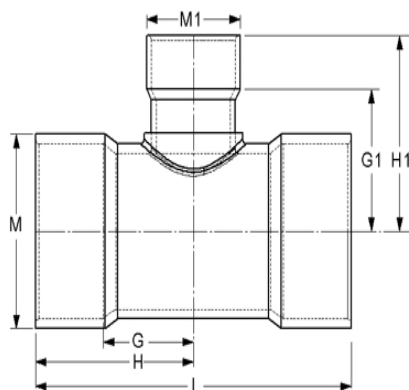

Type Reducing Vent Tee
Schedule SCH 80 DWV
Connection Socket x Socket x Socket

G1 = 11-1/16

H = 14-1/8

H1 = 13-5/16

L = 28-1/4

M = 17-11/16

M1 = 5-3/16

G = 6-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

