

Part No: 3901-756C

**Fabricated CPVC Schedule 80 Tees
DWV**

Desc: 16X6 CPVC RED TEE SOC SCH80

MSRP: 8707.47

Part Code: 099

Weight(lbs): 89.675

Weight(kg): 40.676

Weight(gm): 40676


Size: 16 X 6

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket x Socket x Socket

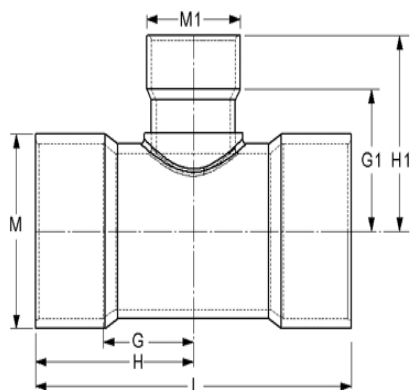

G = 8-5/8

G1 = 11-7/16

H = 16-5/8

H1 = 14-11/16

L = 33-1/4

M = 17-11/16

M1 = 7-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

