

Part No: 3901-762

Fabricated DWV

Tees

Desc: 16X12 PVC RED TEE SOC SCH80

MSRP: 2867.23

Part Code: 400

Weight(lbs): 103.41


Weight(kg): 46.906

Weight(gm): 46906

Size: 16 X 12

Color: GRAY

Material: PVC

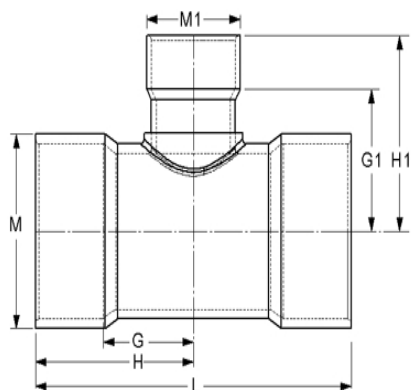

Type Reducing Vent Tee
Schedule SCH 80 DWV
Connection Socket x Socket x Socket

G = 11- 5/8

G1 = 12-5/16

H = 19- 5/8

H1 = 18-9/16

L = 39- 1/4

M = 17-11/16

M1 = 14- 1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

