

Part No: 3901-784

Fabricated DWV

Tees

Desc: 18X4 PVC RED TEE SOC SCH80

MSRP: 1850.3

Part Code: 400

Weight(lbs): 96.785


Weight(kg): 43.901

Weight(gm): 43901

Size: 18 X 4

Color: GRAY

Material: PVC

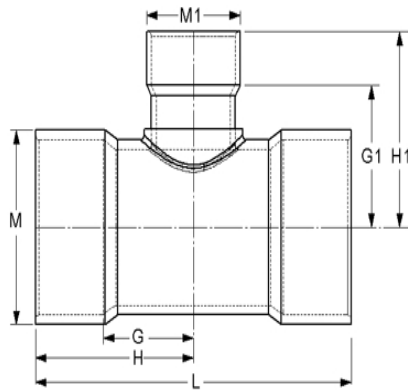

Type Reducing Vent Tee
Schedule SCH 80 DWV
Connection Socket x Socket x Socket

G = 6-7/8 **G1** = 11-15/16 **H** = 15-7/8 **H1** = 14-3/16 **L** = 31-3/4
M = 19-7/8 **M1** = 5-3/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

