

Part No: 3901-820C

Fabricated CPVC Schedule 80 Tees
DWV

Desc: 20X10 CPVC RED TEE SOC SCH80

MSRP: 17936.01

Part Code: 099

Weight(lbs): 163.424

Weight(kg): 74.128

Weight(gm): 74128


Size: 20 X 10

Color: GRAY

Material: CPVC

Type Reduction

Connection Socket x Socket x Socket

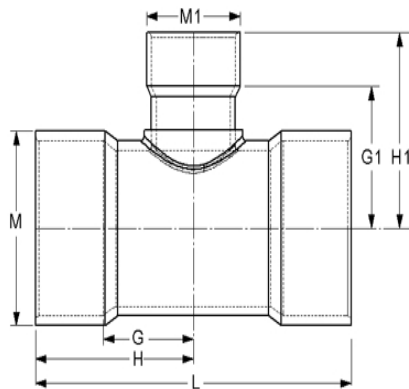

G = 10-7/8

G1 = 14-1/8

H = 20-7/8

H1 = 19-3/8

L = 41-3/4

M = 22-1/16

M1 = 11-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

