

Part No: 3906-060LSCF

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 6 CPVC LNG/SWP 90 ELL SOC SCH80

MSRP: 454.86

Part Code: 099

Weight(lbs): 11.773

Weight(kg): 5.34

Weight(gm): 5340


Size: 6

Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 90° Long Sweep

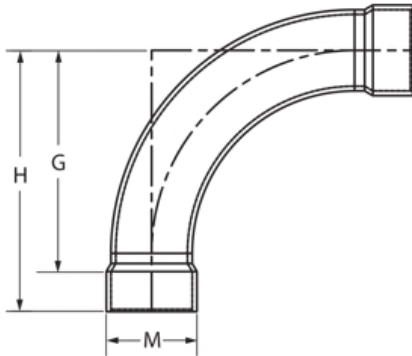

G = 13

H = 16-1/4

M = 7-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

