

Part No: 3909-140

Fabricated DWV

Elbows

Desc: 14 PVC 90 ST ELL SPIGOTXSOC SCH80

MSRP: 1856.88

Part Code: 400

Weight(lbs): 71.011


Weight(kg): 32.21

Weight(gm): 32210

Size: 14

Color: GRAY

Material: PVC

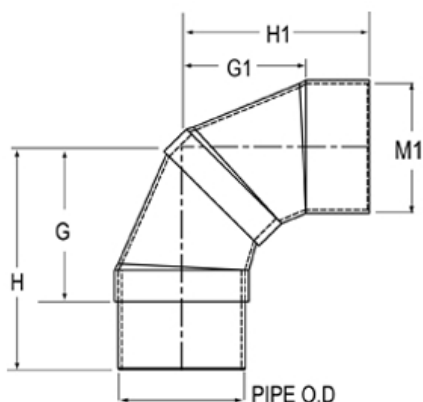

Schedule SCH 80 DWV
Connection Spigot x Socket
Angle 90° Street

G = 13-1/2

G1 = 13-1/2

H = 20-1/2

H1 = 20-1/2

M1 = 15-1/2

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

