

Part No: 3911-060

Fabricated DWV

Elbows

Desc: 6 PVC 11-1/4 ELL SOC SCH80

MSRP: 166.82

Part Code: 400

Weight(lbs): 4.678


Weight(kg): 2.122

Weight(gm): 2122

Size: 6

Color: GRAY

Material: PVC

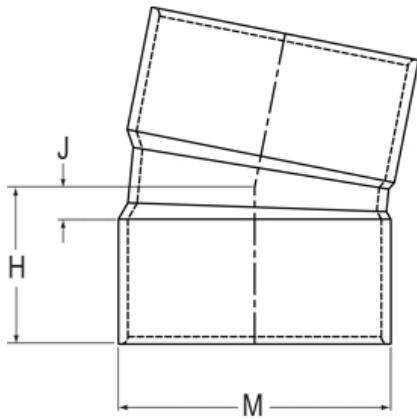

H = 4-1/4

J = 1

M = 7-1/2

Schedule SCH 80 DWV
Connection Socket x Socket
Angle 11-1/4°

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

