

Part No: 3911-100

Fabricated DWV

Elbows

Desc: 10 PVC 11-1/4 ELL SOC SCH80

MSRP: 483.96

Part Code: 400

Weight(lbs): 15.446


Weight(kg): 7.006

Weight(gm): 7006

Size: 10

Color: GRAY

Material: PVC

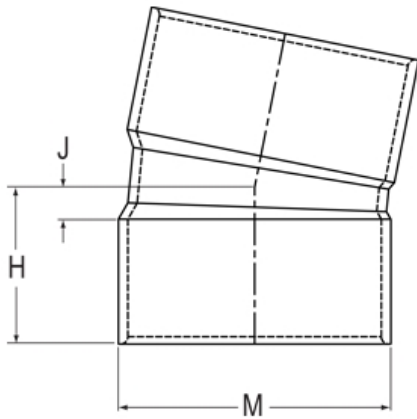

Schedule SCH 80 DWV
Connection Socket x Socket
Angle 11-1/4°

H = 6-11/16

J = 1-7/16

M = 11-15/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

