

**Part No:** 3911-100C

**Fabricated CPVC Schedule 80 Elbows  
DWV**

**Desc:** 10 CPVC 11-1/4 ELL SOC SCH80

**MSRP:** 1011.82

**Part Code:** 099

**Weight(lbs):** 15.829

**Weight(kg):** 7.18

**Weight(gm):** 7180


**Size:** 10

**Color:** GRAY

**Material:** CPVC

**Connection** Socket x Socket

**Angle** 11-1/4°

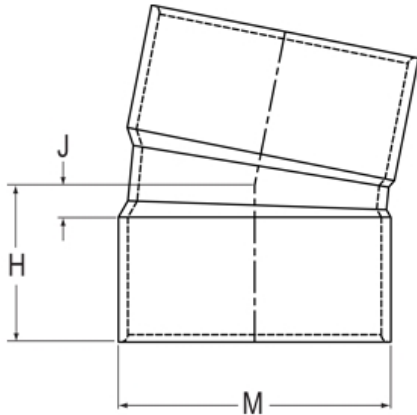

**H** = 6-11/16

**J** = 1-7/16

**M** = 11-15/16

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

