

Part No: 3911-120C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 12 CPVC 11-1/4 ELL SOC SCH80

MSRP: 1694.67

Part Code: 099

Weight(lbs): 29.079

Weight(kg): 13.19

Weight(gm): 13190


Size: 12

Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 11-1/4°

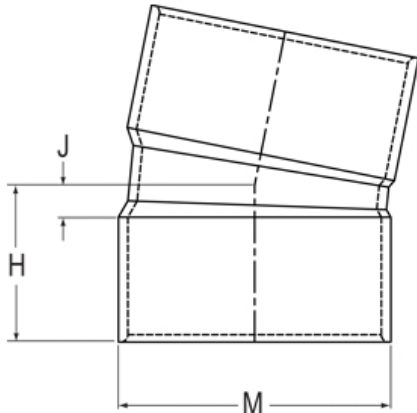

J = 1-9/16

M = 14-1/8

H = 7-13/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

