

Part No: 3911-140

Fabricated DWV

Elbows

Desc: 14 PVC 11-1/4 ELL SOC SCH80

MSRP: 1082.86

Part Code: 400

Weight(lbs): 33.03


Weight(kg): 14.982

Weight(gm): 14982

Size: 14

Color: GRAY

Material: PVC

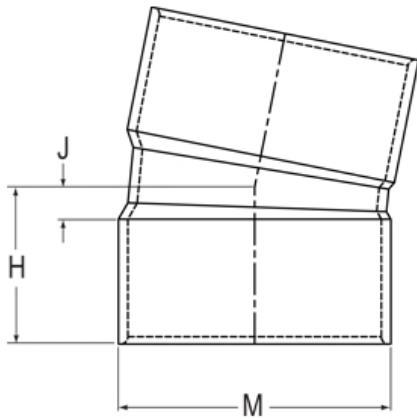

H = 9

J = 2

M = 15-1/2

Schedule SCH 80 DWV

Connection Socket x Socket

Angle 11-1/4°

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

