

Part No: 3915-060C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 6 CPVC 30 ELL SOC

MSRP: 308.49

Part Code: 390

Weight(lbs): 5.432

Weight(kg): 2.464

Weight(gm): 2464


Size: 6

Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 30°

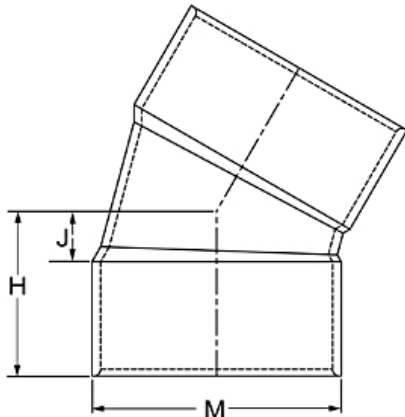

H = 4-7/8

J = 1-5/8

M = 7-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

