

Part No: 3916-080

Fabricated DWV

Elbows

Desc: 8 PVC 22-1/2 ELL SOC SCH80

MSRP: 273.08

Part Code: 400

Weight(lbs): 7.072

Weight(kg): 3.208

Weight(gm): 3208

Size: 8


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket x Socket

Angle 22-1/2°

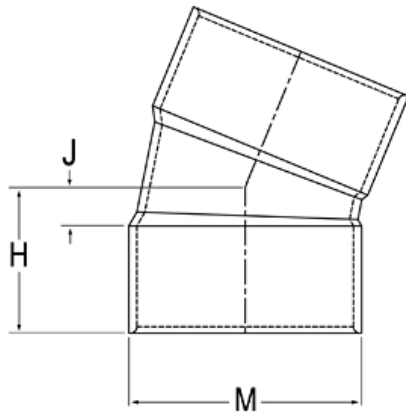

H = 5-7/8

J = 1-5/8

M = 9-5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

