

Part No: 3916-080C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 8 CPVC 22-1/2 ELL SOC SCH80

MSRP: 557.42

Part Code: 099

Weight(lbs): 9.37

Weight(kg): 4.25

Weight(gm): 4250


Size: 8

Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 22-1/2°

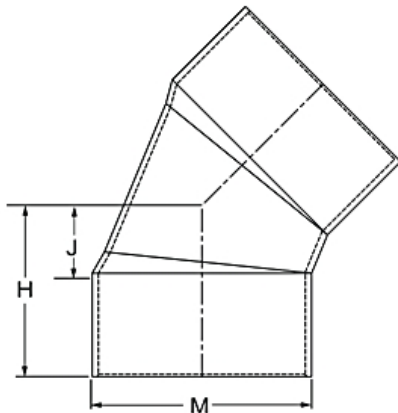

H = 5-7/8

J = 1-5/8

M = 9-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

