

Part No: 3916-240

Fabricated DWV

Elbows

Desc: 24 PVC 22-1/2 ELL SOC SCH80

MSRP: 2741.97

Part Code: 400

Weight(lbs): 190.127

Weight(kg): 86.24

Weight(gm): 86240

Size: 24


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket x Socket

Angle 22-1/2°

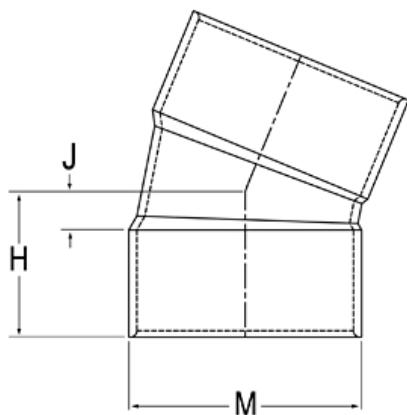

H = 17-3/16

J = 5-3/16

M = 26-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

