

Part No: 3918-180

Fabricated DWV

Elbows

Desc: 18 PVC 15 ELL SOC SCH80

MSRP: 1868.59

Part Code: 400

Weight(lbs): 72.744

Weight(kg): 32.996

Weight(gm): 32996

Size: 18


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket x Socket

Angle 15°

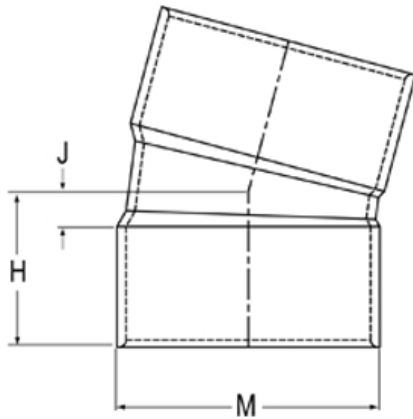

H = 12-1/16

J = 3-1/16

M = 19-7/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

