

Part No: 3918-200

Fabricated DWV

Elbows

Desc: 20 PVC 15 ELL SOC SCH80

MSRP: 2395.51

Part Code: 400

Weight(lbs): 99.283

Weight(kg): 45.034

Weight(gm): 45034

Size: 20


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Socket x Socket

Angle 15°

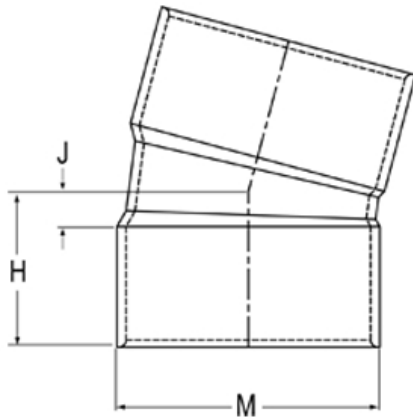

H = 13-1/2

J = 3-1/2

M = 22-1/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

