

Part No: 3920-080C

Fabricated CPVC Schedule 80 Crosses
DWV

Desc: 8 CPVC CROSS SOC SCH80

MSRP: 2421.38

Part Code: 099

Weight(lbs): 30.843

Weight(kg): 13.99

Weight(gm): 13990


Size: 8

Color: GRAY

Material: CPVC

Type Standard

Connection Soc x Soc x Soc x Soc

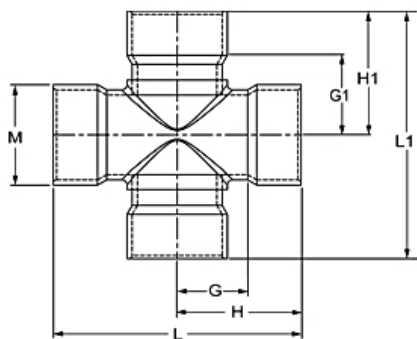

L = 23-3/4

L1 = 23-3/4

M = 9-5/8

G = 7-5/8

G1 = 7-5/8

H = 11-7/8

H1 = 11-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

