

Part No: 3920-120

Fabricated DWV

Crosses

Desc: 12 PVC CROSS SOC SCH80

MSRP: 2022.9

Part Code: 400

Weight(lbs): 89.894

Weight(kg): 40.775

Weight(gm): 40775

Size: 12


Color: GRAY

Material: PVC

Type Standard

Schedule SCH 80 DWV

Connection Soc x Soc x Soc x Soc

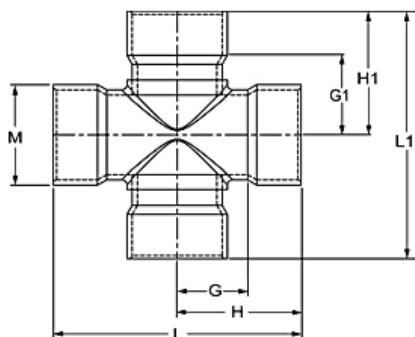

H1 = 17-1/2

H = 17-1/2

G1 = 11-1/4

G = 11-1/4

L = 35

L1 = 35

M = 14-1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

