

Part No: 3920-140

Fabricated DWV

Crosses

Desc: 14 PVC CROSS SOC SCH80

MSRP: 3596.89

Part Code: 400

Weight(lbs): 115.599

Weight(kg): 52.435

Weight(gm): 52435

Size: 14


Color: GRAY

Material: PVC

Type Standard

Schedule SCH 80 DWV

Connection Soc x Soc x Soc x Soc

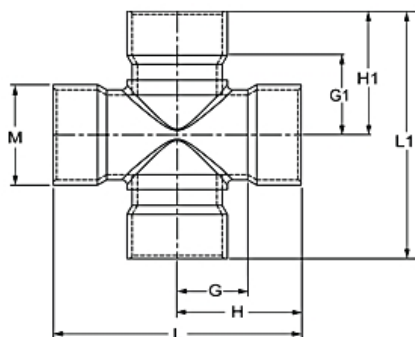

H1 = 19-1/4

H = 19-1/4

G1 = 12-1/4

G = 12-1/4

L = 38-1/2

L1 = 38-1/2

M = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

