

Part No: 3920-532

Fabricated DWV

Crosses

Desc: 6X4 PVC RED CROSS SOC SCH80

MSRP: 401.7

Part Code: 400

Weight(lbs): 11.883


Weight(kg): 5.39

Weight(gm): 5390

Size: 6 X 4

Color: GRAY

Material: PVC

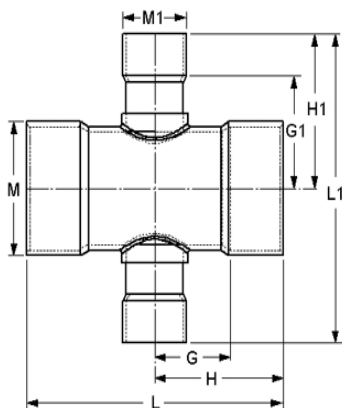

Type Reduction
Schedule SCH 80 DWV
Connection Soc x Soc x Soc x Soc

G = 5- 1/4 **G1** = 6-3/4 **H** = 8- 1/2 **H1** = 9 **L** = 17
L1 = 18 **M** = 7- 1/2 **M1** = 5- 3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

