

Part No: 3920-578

Fabricated DWV

Crosses

Desc: 8X2 PVC RED CROSS SOC SCH80

MSRP: 364.21

Part Code: 400

Weight(lbs): 13.007


Weight(kg): 5.9

Weight(gm): 5900

Size: 8 X 2

Color: GRAY

Material: PVC

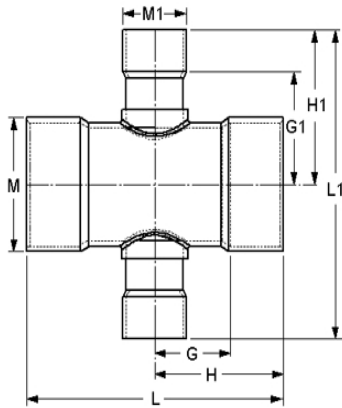

Type Reduction
Schedule SCH 80 DWV
Connection Soc x Soc x Soc x Soc

G = 4-11/16 **G1** = 6-1/8 **H** = 8-15/16 **H1** = 7-7/8 **L** = 17-7/8
L1 = 15-3/4 **M1** = 2-13/16 **M** = 9-5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

