

Part No: 3920-626

Fabricated DWV

Crosses

Desc: 10X6 PVC RED CROSS SOC SCH80

MSRP: 955.74

Part Code: 400

Weight(lbs): 31.023


Weight(kg): 14.072

Weight(gm): 14072

Size: 10 X 6

Color: GRAY

Material: PVC

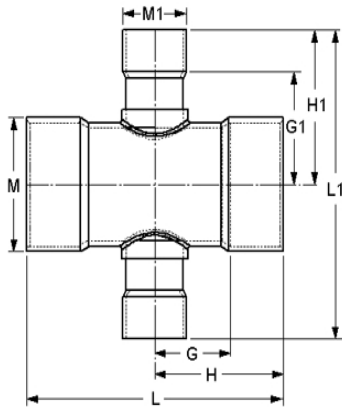

Type Reduction
Schedule SCH 80 DWV
Connection Soc x Soc x Soc x Soc

L = 22-1/4 **L1** = 24-5/8 **M** = 11-15/16 **M1** = 7-1/2 **G** = 5-7/8
G1 = 9-1/16 **H** = 11-1/8 **H1** = 12-5/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

