

Part No: 3920-693

Fabricated DWV

Crosses

Desc: 14X3 PVC RED CROSS SOC SCH80

MSRP: 1492.59

Part Code: 400

Weight(lbs): 46.738


Weight(kg): 21.2

Weight(gm): 21200

Size: 14 X 3

Color: GRAY

Material: PVC

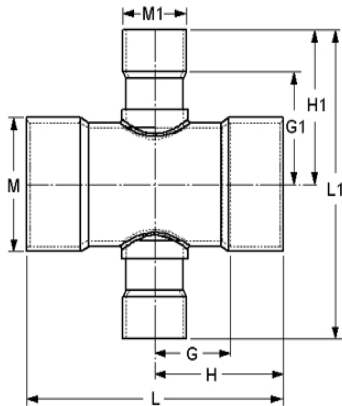

Type Reduction
Schedule SCH 80 DWV
Connection Soc x Soc x Soc x Soc

G = 5-3/4 **G1** = 9-1/8 **H** = 12-3/4 **H1** = 11-3/8 **L** = 25-1/2
L1 = 22-3/4 **M** = 15-1/2 **M1** = 4-1/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

