

Part No: 3920-792

Fabricated DWV

Crosses

Desc: 18X12 PVC RED CROSS SOC SCH80

MSRP: 4599.27

Part Code: 400

Weight(lbs): 147.333


Weight(kg): 66.829

Weight(gm): 66829

Size: 18 X 12

Color: GRAY

Material: PVC

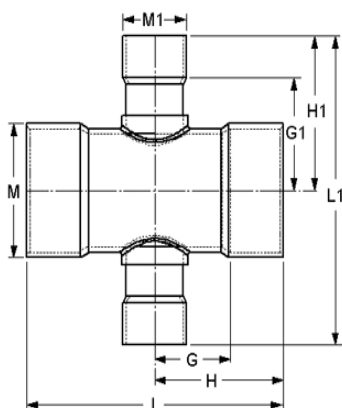

Type Reduction

Schedule SCH 80 DWV

Connection Soc x Soc x Soc x Soc

H1 = 19-7/16

L = 41

L1 = 38-7/8

M = 19-7/8

M1 = 14-1/8

G = 11-1/2

G1 = 13-3/16

H = 20-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

