

Part No: 3920-816C

**Fabricated CPVC Schedule 80 Crosses
DWV**

Desc: 20X6 CPVC RED CROSS SOC SCH80

MSRP: 16448.32

Part Code: 099

Weight(lbs): 165.303


Weight(kg): 74.98

Weight(gm): 74980

Size: 20 X 6

Color: GRAY

Material: CPVC

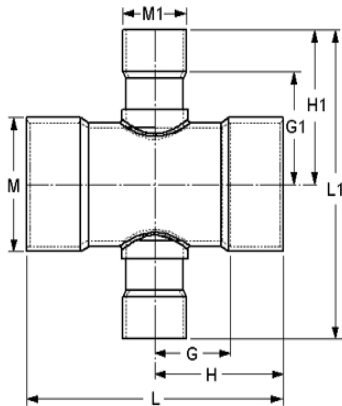

Type Reduction

Connection Soc x Soc x Soc x Soc

G = 8-7/8

G1 = 13-1/4

H = 18-7/8

H1 = 16-1/2

L = 37-3/4

L1 = 33

M = 22-1/16

M1 = 7-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

