

Part No: 3920-826

Fabricated DWV

Crosses

Desc: 20X16 PVC RED CROSS SOC SCH80

MSRP: 6478.77

Part Code: 400

Weight(lbs): 238.26


Weight(kg): 108.073

Weight(gm): 108073

Size: 20 X 16

Color: GRAY

Material: PVC

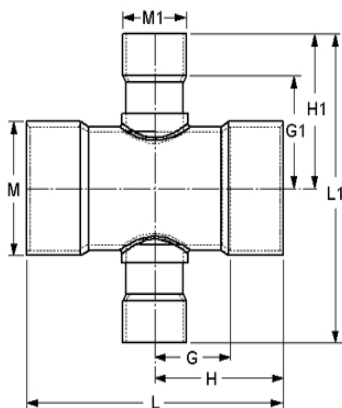

Type Reduction

Schedule SCH 80 DWV

Connection Soc x Soc x Soc x Soc

M = 22-1/16

M1 = 17-11/16

G = 14

G1 = 15-1/8

H = 24

H1 = 23-1/8

L = 48

L1 = 46-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

