

Part No: 3920-908C

**Fabricated CPVC Schedule 80 Crosses
DWV**

Desc: 24X8 CPVC RED CROSS SOC SCH80

MSRP: 26797.08

Part Code: 099

Weight(lbs): 275.92

Weight(kg): 125.155

Weight(gm): 125155


Size: 24 X 8

Color: GRAY

Material: CPVC

Type Reduction

Connection Soc x Soc x Soc x Soc

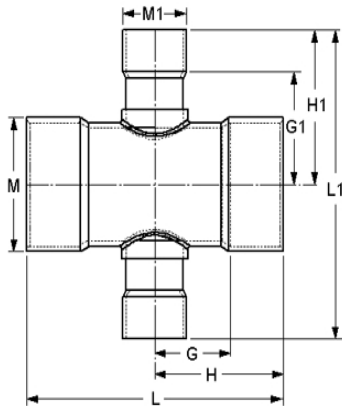

G = 10-1/4

G1 = 15-15/16

H = 22-1/4

H1 = 20-3/16

L = 44-1/2

L1 = 40-3/8

M = 26-7/16

M1 = 9-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

