

Part No: 3927-100C

**Fabricated CPVC Schedule 80 Elbows
DWV**

Desc: 10 CPVC 45 ST ELL SPIGOTXSOC SCH80

MSRP: 1436.19

Part Code: 099

Weight(lbs): 26.279

Weight(kg): 11.92

Weight(gm): 11920


Size: 10

Color: GRAY

Material: CPVC

Connection Spigot X Socket

Angle 45° Street

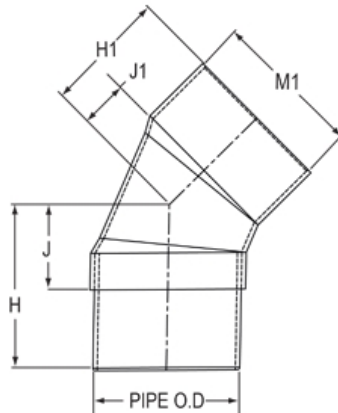

H = 11-15/16

H1 = 8-11/16

J = 5-15/16

J1 = 3-7/16

M = 11-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

