

Part No: 3927-140

Fabricated DWV

Elbows

Desc: 14 PVC 45 ST ELL SPIGOTXSOC SCH80

MSRP: 1130.63

Part Code: 400

Weight(lbs): 41.286

Weight(kg): 18.727

Weight(gm): 18727

Size: 14


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Connection Spigot x Socket

Angle 45° Street

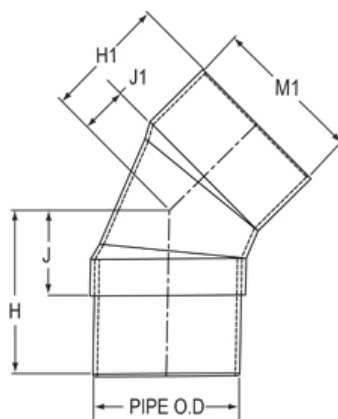

H = 11-9/16

H1 = 11-9/16

J = 4-9/16

J1 = 4-9/16

M1 = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

