

Part No: 3928-120

Fabricated DWV

Couplings

Desc: 12 PVC REPAIR COUP GASKET SCH80

MSRP: 558.46

Part Code: 400

Weight(lbs): 49.214

Weight(kg): 22.323

Weight(gm): 22323


Size: 12

Color: GRAY

Material: PVC

Schedule SCH 80 DWV - Repair

Connection Gasket x Gasket

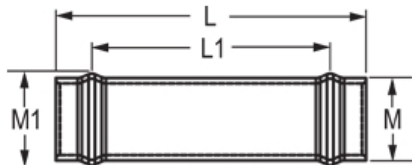

L1 = 21-3/8

M = 14-1/8

M1 = 15-3/8

L = 29

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

