

Part No: 3928-200

Fabricated DWV

Couplings

Desc: 20 PVC REPAIR COUP GASKET SCH80

MSRP: 2894.02

Part Code: 400

Weight(lbs): 113.32

Weight(kg): 51.401

Weight(gm): 51401


Size: 20

Color: GRAY

Material: PVC

Schedule SCH 80 DWV - Repair

Connection Gasket x Gasket

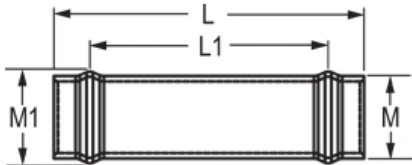

L = 32

L1 = 23-1/2

M = 22-1/16

M1 = 24-1/16

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

