

Part No: 3928-200C

**Fabricated CPVC Schedule 80 Couplings
DWV**

Desc: 20 CPVC REPAIR COUPLING GASKET SCH80

MSRP: 9456.43

Part Code: 099

Weight(lbs): 160.532

Weight(kg): 72.816

Weight(gm): 72816

Size: 20


Color: GRAY

Material: CPVC

Type Repair

Connection Gasket x Gasket

Note L1 = Gasket to Gasket

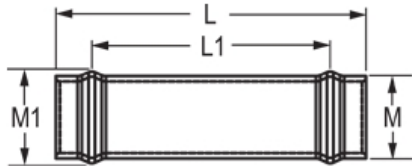

L = 32

L1 = 23-1/2

M = 22-1/16

M1 = 24-1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

